

減壓閥, 速度控制閥, 止逆閥, 梭動閥

Humphrey

進口代理商品

TAC級

規格：

各種性能	型號	RSR 減壓閥	SC1 速度 控制閥	C1 止逆閥	C125 止逆閥	S125 梭動閥
配管口徑尺寸		NPT 1/8"陰 #10-32陽	#10-32陰	#10-32	NPT 1/8"	NPT 1/8"
使用流體		空氣				
使用壓力範圍 MPa		0~0.9	0.02~0.9	0.03~0.9	0.003~0.9	0.003~0.9
有效斷面積 mm ²				5.5	5.5	6
周圍溫度		-7~+65°C				
油潤滑		不要				

訂購代號：

例 C125 w/VAI


性能 分類 編碼 型號	使用 Viton油封 w/VAI
RSR減壓閥	NA
SC1速度控制閥	NA
C1止逆閥	NA
C125止逆閥	SP
S125梭動閥	SP

大氣壓下之空氣流量：



型號 流量值 LPM 使用壓力	RSR 減壓閥	SC1 速度 控制閥	C1 止逆閥	C125 止逆閥	S125 梭動閥
0.2 MPa			91.0	198.0	170.0
0.35 MPa			133.0	283.0	255.0
0.55 MPa			198.0	453.0	368.0
0.7 MPa	進氣口(IN)		232.0	538.0	453.0
	#10時	1/8"時			
	311	622			

外觀尺寸：


RSR
減壓閥

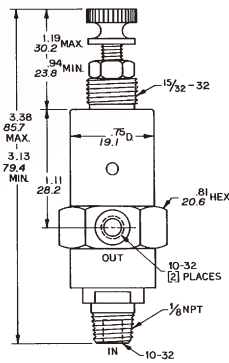



SC1
速度控制閥

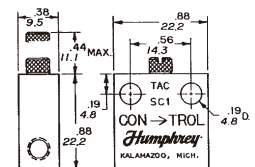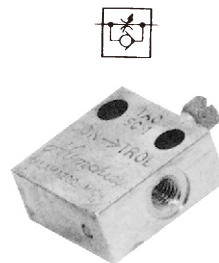

C1
止逆閥

 

C125
止逆閥

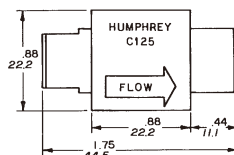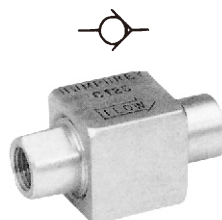

S125
梭動閥

