

DP* 系列


DC空氣幫浦




進口代理商品




DP0102

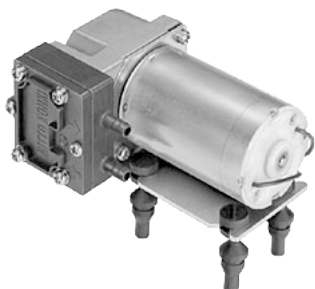

DP0105

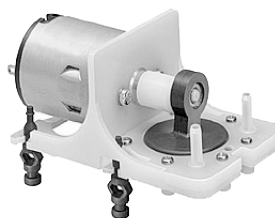

DP0125

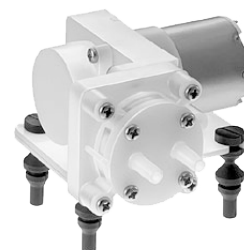

DP0140

規格：

型號	DP0102	DP0105	DP0125	DP0140
達到真空度	(-200mmHg) -26.7kPa (-267mbar) (-7.87in.Hg)	(-500mmHg) -66.6kPa (-666mbar) (-19.68in.Hg)	(-250mmHg) -33.3kPa (-333mbar) (-9.84in.Hg)	(-400mmHg) -53.3kPa (-533mbar) (-15.7in.Hg)
開放時流量	5ℓ/min(0.177cfm)	2.8ℓ/min(0.1cfm)	2.5ℓ/min(0.088cfm)	4ℓ/min(0.141cfm)
額定電壓	12V	24V	12V	12V
最高壓力	(0.45kgf/cm ²) 0.045MPa (0.45bar) (6.4psig)	(2.5kgf/cm ²) 0.25MPa (2.5bar) (36psig)	(0.3kgf/cm ²) 0.03MPa (0.3bar) (4.27psig)	(0.5kgf/cm ²) 0.05MPa (0.5bar) (7.1psig)
毛重 kg(Lbs.)	0.25(0.55)	0.36(0.80)	0.08(0.18)	0.19(0.42)
尺寸 mm (※)	41(W)×68(L)×77(H)	63(W)×94(L)×43(H)	42(W)×77(L)×36(H)	90(W)×84(L)×43(H)

※ 尺寸不包含避震腳