

# MS\* 系列 套筒(母頭)

快速接頭




MSM...




MSM...A (one touch type)




MSM (外牙型)

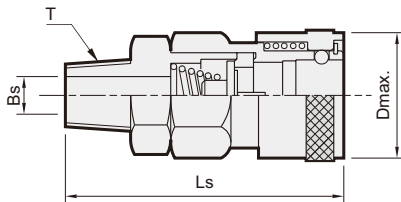


MSF (內牙型)

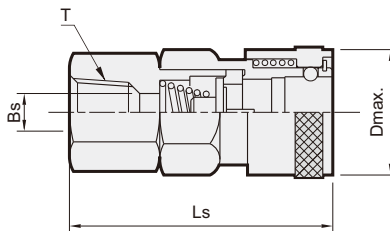

MSH (軟管接頭型)

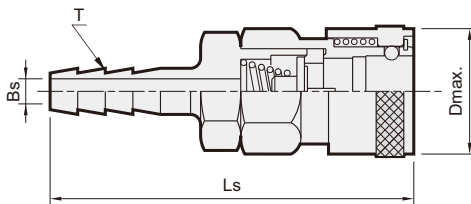

MSP (螺帽型)

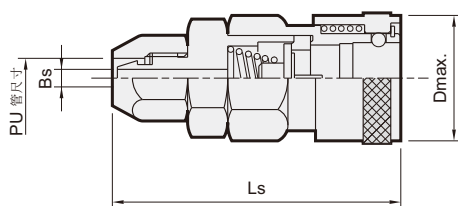

訂購代號：

MSM - 20 - A - S

型號

MSM	
MSF	
MSH	
MSP	

20  
30  
40

S : 鋼材  
B : 銅材

A : One touch type  
無 : 標準型

型號	螺牙尺寸 T	尺寸 (mm)			重量 (g)	
		Bs	D <sub>max.</sub>	Ls	鋼	銅
MSM-20	R1/4	φ 7.5	φ 25	55.5	95	104
MSM-30	R3/8	φ 7.5	φ 25	57.5	100	109
MSM-40	R1/2	φ 9	φ 25	59.5	110	117

型號	螺牙尺寸 T	尺寸 (mm)			重量 (g)	
		Bs	D <sub>max.</sub>	Ls	鋼	銅
MSF-20	Rc1/4	φ 7.5	φ 25	52.5	104	110
MSF-30	Rc3/8	φ 7.5	φ 25	54.5	103	111
MSF-40	Rc1/2	φ 9	φ 25	54.5	122	131

型號	軟管尺寸 T	尺寸 (mm)			重量 (g)	
		Bs	D <sub>max.</sub>	Ls	鋼	銅
MSH-20	5/16"Hose	φ 5	φ 25	72.5	95	104
MSH-30	3/8"Hose	φ 7.5	φ 25	76.5	100	106
MSH-40	1/2"Hose	φ 9	六角 26/30	78.5	110	117

型號	Pu尺寸 內徑×外徑 (mm)	尺寸 (mm)			重量 (g)	
		Bs	D <sub>max.</sub>	Ls	鋼	銅
MSP-20	5×8	φ 4	φ 25	56.5	100	106
MSP-30	6.5×10	φ 5	φ 26	58	110	116
MSP-40	8×12	φ 6	φ 26	59	110	116