


VP* 系列

活塞式真空幫浦



進口代理商品

10W

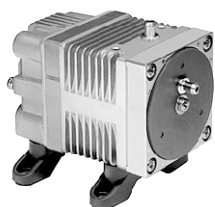

VP0125/VP0140


40W



VP0435A

規格：

型號	VP0125	VP0140
達到真空度	(-250mmHg) -33.3kPa (-333mbar) (-9.84in.Hg)	(-400mmHg) -53.3kPa (-533mbar) (-15.7in.Hg)
開放時流量	7ℓ/min(0.247cfm)	3ℓ/min(0.106cfm)
消費電力	15W	
毛重 kg(Lbs.)	0.7(1.54)	
尺寸 mm	75(W)×101(L)×90(H)	

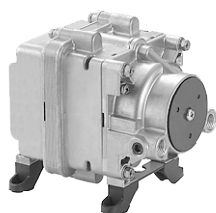

VP0450

型號	VP0435A	VP0450
達到真空度	(-350mmHg) -46.7kPa (-467mbar) (-13.78in.Hg)	(-500mmHg) -66.7kPa (-667mbar) (-19.68in.Hg)
開放時流量	25ℓ/min(0.88cfm)	18ℓ/min(0.635cfm)
消費電力	39W	35W
毛重 kg(Lbs.)	2.3(5.1)	2.2(4.84)
尺寸 mm	106(W)×161(L)×122(H)	104(W)×148(L)×131(H)

60W



VP0625

70W



VP0660

規格：


型號	VP0625	VP0660
達到真空度	(-250mmHg) -33.3kPa (-333mbar) (-9.84in.Hg)	(-600mmHg) -80kPa (-800mbar) (-23.6in.Hg)
開放時流量	40ℓ/min(1.41cfm)	25ℓ/min(0.88cfm)
消費電力	60W	70W
毛重 kg(Lbs.)	3(6.6)	5(11)
尺寸 mm	118(W)×175(L)×138(H)	150(W)×206(L)×154(H)

90W



VP0940

120W

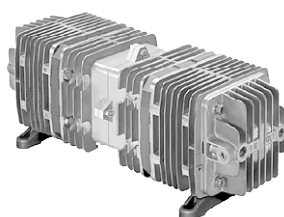

VP0660 × 2

規格：

型號	VP0940	VP0660 × 2	
達到真空度	(-400mmHg) -53.3kPa (-533mbar) (-15.7in.Hg)	Series connection (-700mmHg) -93.3kPa (-933mbar) (-27.5in.Hg)	Parallel connection (-600mmHg) -80kPa (-800mbar) (-23.6in.Hg)
開放時流量	60ℓ/min(2.12cfm)	25ℓ/min(0.88cfm)	50ℓ/min(1.76cfm)
消費電力	95W	125W	
毛重 kg(Lbs.)	4.55(10)	10(22)	
尺寸 mm	150(W)×193(L)×154(H)	150(W)×396(L)×154(H)	