

海棉質-真空吸盤

PISCO

真空吸盤

進口代理商品

海棉質 (Sponge Type)

包裝：1個/袋

訂購代號：

VPA 10 S S 6J - FH - F15 - □

1 2 3 4 5 6 7 8

① 固定座型號

② 吸盤徑： (mm)

編號	10	15	20	25	30	35	50	70	100
尺寸	φ10	φ15	φ20	φ25	φ30	φ35	φ50	φ70	φ100

③ 吸盤型狀：S：海棉質吸盤

④ 吸盤材質：S：矽橡膠/無記號：橡膠

⑤ 接頭型式/尺寸：(*只提供小型吸盤的支架) (mm)

吸盤徑	φ10~φ30		φ10~φ50		φ70~φ100
接頭型式	快速配管接頭	倒鉤型接頭	快速配管接頭	倒鉤型接頭	管用錐型內牙
尺寸	4×2.5	4×2.5	6×4	6×4	Rc(G)1/8
編號	4J*	4B*	6J	6B	01

⑥ 具偏擺固定座：(選用配備，須另付費；不適用S3材質)

FH：偏擺角度30° / FHH：偏擺角度15° / ECV：防掉落閘(僅適φ1.5~50mm)

⑦ 具過濾器：(選用配備，須另付費；不適用S3材質)

F15：吸盤直徑φ10~25mm / F30：吸盤直徑φ30~50mm

⑧ 金屬部位材質：

S3：銅製材質(環為深藍色)/無記號：標準材質







VPA SPONGE 固定式&配管口徑向上 Fixed Type On-the-top Vacuum Port		VPA SPONGE / S3 固定式&配管口徑向上 Fixed Type On-the-top Vacuum Port		VPF SPONGE 活動式&直接配置型 Spring & Direct Mounting Type	
型式		型式		型式	
VPA10S□6J	VPA35□S6J	VPA10S□6J-S3	VPA35□S6J-S3	VPF10S□	VPF30S□
VPA15S□6J	VPA50□S6J	VPA15S□6J-S3	VPA50□S6J-S3	VPF15S□	VPF35S□
VPA20S□6J	VPA70□S01	VPA20S□6J-S3	VPA70□S01-S3	VPF20S□	VPF50S□
VPA25S□6J	VPA100□S01	VPA25S□6J-S3	VPA100□S01-S3	VPF25S□	
VPA30S□6J		VPA30S□6J-S3			
VPB SPONGE 固定式&配管口徑側向 Fixed Type On-the-side Vacuum Port		VPB SPONGE / S3 固定式&配管口徑側向 Fixed Type On-the-side Vacuum Port		VPF SPONGE / S3 活動式&直接配置型 Spring & Direct Mounting Type	
型式		型式		型式	
VPB10S□6J	VPB35S□6J	VPB10S□6J-S3	VPB35S□6J-S3	VPF10S□-S3	VPF30S□-S3
VPB15S□6J	VPB50S□6J	VPB15S□6J-S3	VPB50S□6J-S3	VPF15S□-S3	VPF35S□-S3
VPB20S□6J	VPB70S□01	VPB20S□6J-S3	VPB70S□01-S3	VPF20S□-S3	VPF50S□-S3
VPB25S□6J	VPB100S□01	VPB25S□6J-S3	VPB100S□01-S3	VPF25S□-S3	
VPB30S□6J		VPB30S□6J-S3			
VPD SPONGE 活動式&配管口徑側向 Spring Type On-the-side Vacuum Port		VPC SPONGE / S3 活動式&配管口徑向上 Spring Type On-the-top Vacuum Port			
型式		型式			
VPD10S□6J	VPD35S□6J	VPC10S□6J-S3	VPC35S□6J-S3		
VPD15S□6J	VPD50S□6J	VPC15S□6J-S3	VPC50S□6J-S3		
VPD20S□6J	VPD70S□01	VPC20S□6J-S3	VPC70S□01-S3		
VPD25S□6J	VPD100S□01	VPC25S□6J-S3	VPC100S□01-S3		
VPD30S□6J		VPC30S□6J-S3			
VP SPONGE 吸盤用(海棉) Pad Rubber Only (Sponge)		VP SPONGE 吸盤用(海棉) Pad Flame Only (Sponge)		VP SPONGE / S3 吸盤用(海棉) Pad Flame Only (Sponge)	
型式		型式		型式	
VP10S□	VP35S□	VP10S□A	VP35S□A	VP10S□A-S3	VP25S□A-S3
VP15S□	VP50S□	VP15S□A	VP50S□A	VP15S□A-S3	VP30S□A-S3
VP20S□	VP70S□	VP20S□A	VP70S□A	VP20S□A-S3	
VP25S□	VP100S□	VP25S□A	VP100S□A		
VP30S□		VP30S□A			
VPC SPONGE 活動式&配管口徑向上 Spring Type On-the-top Vacuum Port		VPD SPONGE / S3 活動式&配管口徑側向 Spring Type On-the-side Vacuum Port			
型式		型式			
VPC10S□6J	VPC35S□6J	VPD10S□6J-S3	VPD35S□6J-S3		
VPC15S□6J	VPC50S□6J	VPD15S□6J-S3	VPD50S□6J-S3		
VPC20S□6J	VPC70S□01	VPD20S□6J-S3	VPD70S□01-S3		
VPC25S□6J	VPC100S□01	VPD25S□6J-S3	VPD100S□01-S3		
VPC30S□6J		VPD30S□6J-S3			

海棉質 / 單層蛇腹型-真空吸盤

PISCO

真空吸盤

進口代理商品

VPMA MINI SPONGE 固定式&配管口徑向上 Fixed Type On-the-top Vacuum Port 		VPMA MINI SPONGE / S3 固定式&配管口徑向上 Fixed Type On-the-top Vacuum Port 	
型式		型式	
VPMA10S□6J	VPMA25S□6J	VPMA10S□6J-S3	VPMA25S□6J-S3
VPMA15S□6J	VPMA30S□6J	VPMA15S□6J-S3	VPMA30S□6J-S3
VPMA20S□6J		VPMA20S□6J-S3	
VPMB MINI SPONGE 固定式&配管口徑側向 Fixed Type On-the-side Vacuum Port 		VPMB MINI SPONGE / S3 固定式&配管口徑側向 Fixed Type On-the-side Vacuum Port 	
型式		型式	
VPMB10S□6J	VPMB25S□6J	VPMB10S□6J-S3	VPMB25S□6J-S3
VPMB15S□6J	VPMB30S□6J	VPMB15S□6J-S3	VPMB30S□6J-S3
VPMB20S□6J		VPMB20S□6J-S3	
VPMC MINI SPONGE 活動式&配管口徑向上 Spring Type On-the-top Vacuum Port 		VPMC MINI SPONGE / S3 活動式&配管口徑向上 Spring Type On-the-top Vacuum Port 	
型式		型式	
VPMC10S□6J	VPMC25S□6J	VPMC10S□6J-S3	VPMC25S□6J-S3
VPMC15S□6J	VPMC30S□6J	VPMC15S□6J-S3	VPMC30S□6J-S3
VPMC20S□6J		VPMC20S□6J-S3	
VPMD MINI SPONGE 活動式&配管口徑側向 Spring Type On-the-side Vacuum Port 		VPMD MINI SPONGE / S3 活動式&配管口徑側向 Spring Type On-the-side Vacuum Port 	
型式		型式	
VPMD10S□6J	VPMD25S□6J	VPMD10S□6J-S3	VPMD25S□6J-S3
VPMD15S□6J	VPMD30S□6J	VPMD15S□6J-S3	VPMD30S□6J-S3
VPMD20S□6J		VPMD20S□6J-S3	

單層蛇腹型

包裝：1個/袋

訂購代號：

VPC 10 B N 6J - QM - FH - F15 - □

1 2 3 4 5 6 7 8 9

① 固定座型號

② 吸盤徑：

編號	6	8	10	15	20	25	30	40	50	60	80	100
尺寸	φ6	φ8	φ10	φ15	φ20	φ25	φ30	φ40	φ50	φ60	φ80	φ100

③ 吸盤形狀：B：單層蛇腹型

④ 吸盤材質：N：腈橡膠 / S：矽橡膠 / U：聚氨酯橡膠 / F：氟橡膠 / SE：抗靜電型矽橡膠 / NE：低阻防靜電NBR / HN：HNBR / EP：EPDM

⑤ 接頭型式/尺寸：(*只提供小型吸盤的支架)

吸盤徑	φ10		φ10~φ30		φ10~φ50		φ80
接頭型式	快速配管	倒鉤型	快速配管	倒鉤型	快速配管	倒鉤型	管用錐型內牙
尺寸	3×2	3×2	4×2.5	4×2.5	6×4	6×4	Rc(G)1/8
編號	3J*	3B*	4J*	4B*	6J	6B	01

⑥ 無痕橡膠附加材質：(選用配備, 須另付費)

QK：PEEK / QM：POM / QKE：導電性PEEK

⑦ 具備擺固定座：(選用配備, 須另付費; 僅適φ10~50mm)


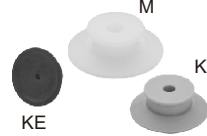

FH：偏擺角度30° / FHH：偏擺角度15° / ECV：防掉落閥

⑧ 具過濾器：(選用配備, 須另付費; 不適S3材質)

F15：吸盤直徑φ10~25mm / F30：吸盤直徑φ30~50mm

⑨ 金屬部位材質：(選用配備, 須另付費)

S3：銅製材質(環為深藍色) / 無記號：標準材質

VP BELLOWS 蛇腹吸盤 Pad Rubber Only F, U, S 		VP-AT BELLOWS 蛇腹吸盤附件 Rubber Attachment Only M, K, KE 		VP BELLOWS 蛇腹吸盤支架 Pad Flame Only 	
型式		型式		型式	
VP6B□	VP30B□□	VP10BQ□-AT	VP25BQ□-AT	VP80B□A	VP100B□A
VP8B□	VP40B□	VP15BQ□-AT	VP30BQ□-AT		
VP10B□□	VP50B□	VP20BQ□-AT			
VP15B□□	VP60B□				
VP20B□□	VP80B□				
VP25B□□	VP100B□				